




## **RIVNUT® B2007**

The RIVNUT® Battery tool

# **BOLLHOFF**

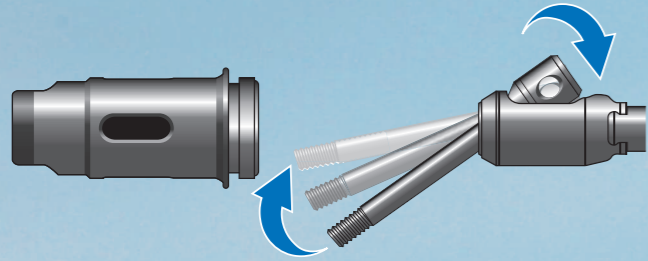

**New quick tooling replacement**

- No tool needed
- Uses the existing mandrel & anvil

**Standard BÖLLHOFF ergonomic**

- Single press trigger function to complete the entire cycle
- Comfortable & ergonomic handling

**Advantages:**

- 3 kN to 22 kN (M3-M10 steel)
- 24 RIVNUT® / min
- Up to 800 cycles with 1 battery
- Internal qualification done with 1 000 000 cycles
- BÖLLHOFF quality
- RIVNUT® nut & stud compatible
- Li-Ion technology battery



YouTube RIVNUT B2007




**Electro-hydraulic technology**

- Well balanced
- Power & reliability in a reasonable weight

**Soft coverings** for comfortable handling and for tool protection

**LCD screen**

- Load adjustment
- Setting parameters menu
- Battery level information

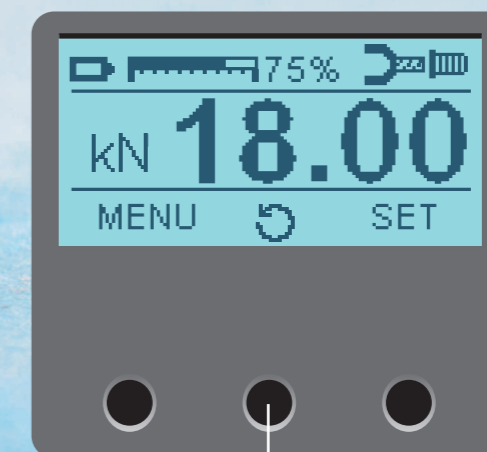

- Unscrewing button



# RIVNUT® B2007 – Cordless battery tool for RIVNUT® nut & studs

## Built for intensive use

- Electro-hydraulic technology: the choice for ultimate performance with the best reliability whilst maintaining a reasonable weight
- Produces 600 to 800 cycles per battery
- 1 000 000 cycles qualification – BÖLLHOFF quality

## Optimized ergonomic design

- Comparable weight to the P2007 when fitted with hose

<b>B2007</b> 	Tool + Tooling + Battery	Total weight
	2,12 + 0,07 + 0,30	<b>2,49 kg</b>
<b>P2007</b>  Pneumatic	Tool + Tooling + Pneumatic	Total weight
	2,20 + 0,07 + 0,33	<b>2,60 kg</b>

- Well balanced tool
- Smart lighting to see in dark conditions




- Precise force adjustment, easy to do from the screen (possibility to lock it in the menu)
- Full menu to personalize your tool to your wish

## Main characteristics

Setting force range kN	RIVNUT® capacity	Setting stroke max	Cadency RIVNUT®/min	Weight (Tool + Tooling + Battery) kg
3 → 22*	Steel: M3 → M10* Stainless steel: M3 → M8*	7 mm	24	2,49

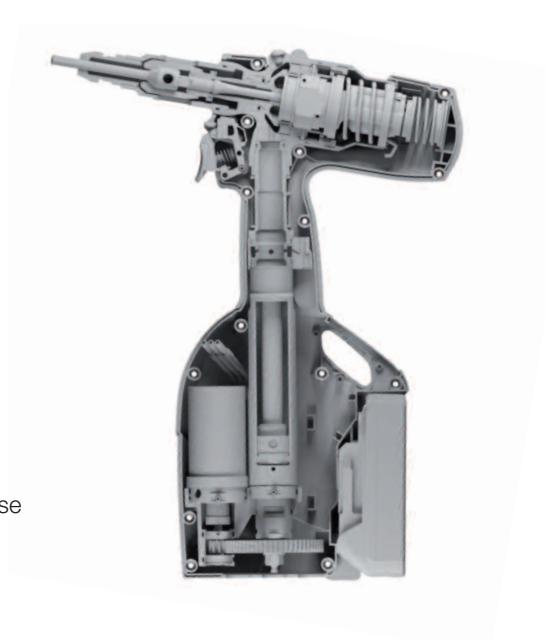

\* Above 18 kN (M10 steel & M8 Stainless steel) please use fork adaptor & specific tooling



 



 
Well balanced

# RIVNUT® B2007



	Connection made for Europe 	Connection made for US 
Package with 1 battery	236 166 01 000	236 168 01 000
Package with 2 batteries	236 167 01 000	236 169 01 000

## Tooling

				3 → 18 kN					18 → 22 kN	
				M3	M4	M5	M6	M8	M8	M10
Mandrel			236 113 XX 020	03	04	05	06	08	236 913 08 110	236 913 10 019
			376 113 XX 020	-	04	05	06	08	-	
Anvil			236 113 XX 030	03	04	05	06	08	08	10
			376 113 XX 030	-	04	05	06	08	-	
Fork and nose for studs & force >18 kN (M8 & M10)			236 166 00 303 236 166 00 304						X	X
 Tooling box			236 113 00 002	X	X	X	X	X	-	

ex: to set M10 RIVNUT® nut, please order the specific nose + fork + mandrel + anvil, so 236 166 00 303 + 236 166 00 304 + 236 113 10 019 + 236 113 10 030

## Accessories

Accessorie	Code	Accessorie	Code
 <b>Original battery</b> 14,4V 2,6AH - Li-Ion	282 590 30 350	 <b>Tool support</b>	236 166 00 308
 <b>Original charger</b>	EU: 282 590 30 352 US: 282 590 30 353	<b>Screw kit adaptor</b>	See general RIVNUT® catalogue 
 <b>Battery with higher capacity</b> 14,4V 4,0AH - Li-Ion	282 590 30 351	 <b>Cord power supply</b>	EU: 282 590 30 356 US: 282 590 30 357
 <b>Multicharger</b> 4 positions	EU: 282 590 30 354 US: 282 590 30 355		

**Böllhoff International with companies in:**

Argentina  
Austria  
Brazil  
Canada  
China  
Czech Republic  
France  
Germany  
Hungary  
India  
Italy  
Japan  
Mexico  
Poland  
Romania  
Russia  
Slovakia  
South Korea  
Spain  
Switzerland  
Thailand  
Turkey  
United Kingdom  
USA

Apart from these 24 countries, Böllhoff supports its international customers in other important industrial markets in close partnership with agents and dealers.

Böllhoff Group  
Please find your local contact on [www.boellhoff.com](http://www.boellhoff.com)  
or contact us under [fasteningtechnology@boellhoff.com](mailto:fasteningtechnology@boellhoff.com)

